

DYMO®

XTL™

Industrial Labelling Solution



SIMPLIFIES THE MOST COMPLEX LABELLING.



This product guide contains
RS Stock Numbers

DYMO[®]

XTL[™]

WE BET YOU'VE NEVER EXPERIENCED INDUSTRIAL LABELLING THIS SIMPLE.

Jobsite tested and packed with features, the DYMO[®] XTL[™] 300 and XTL 500 label makers help simplify industrial labelling for a more efficient, frustration-free experience. By incorporating cues from today's technology, XTL label makers offer a familiarity that makes using them easy. That's why over 80% of people who used an XTL label maker for eight weeks without any training said it performed better than their current label maker*. Built to meet your needs, DYMO XTL label makers offer the flexibility to print continuous tape, pre-sized labels, heat-shrink tubes and small format safety signage all from the same label maker. A full range of durable XTL labels are also available in a variety of materials and colours that fit with OSHA, ANSI and ISO colour standards for workplace communication and safety.

Read on to see how XTL label makers are redefining simplicity.

LIFE-LIKE ON SCREEN PRINT PREVIEW

and colour display shows exactly how labels will look when applied to cables, pipes, panels, and more



* Based on in-field use study

BUILT-IN LABEL APPLICATIONS

simply select an application from the Home screen to get started quickly



TOUCH SCREEN

helps make label creation easier and faster


(available only on XTL 500)



PRE-LOADED LABEL TEMPLATES

create labels 3x faster* and ensure perfect formatting to save time.

Also includes pre-set layouts for almost 100 patch panel models to eliminate size and spacing guesswork.

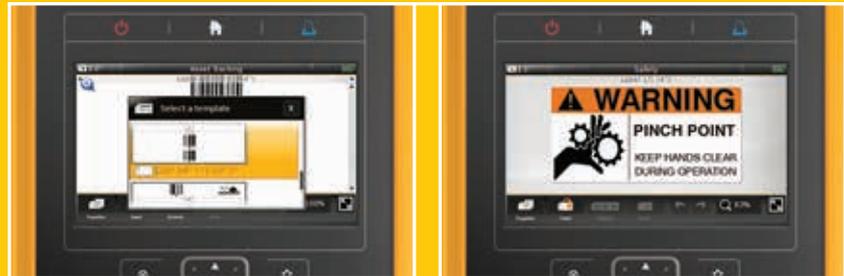

ADDITIONAL FEATURES INCLUDE:

- 1 3-Year Limited Warranty + 1 additional year upon registering online
- 2 Maximised print area helps reduce label waste
- 3 PC-connectivity to easily transfer labels to and from DYMO ID software for jobsite editing and printing
- 4 FREE DYMO ID software adds even more capability to your XTL label maker
- 5 Durable built-in cutter for fast label production
- 6 Impact-resistant rubber bumpers and wipe-clean keypad withstands harsh environments
- 7 On-screen label indicator automatically detects and displays the loaded label
- 8 Customisable printer settings eliminate unnecessary menus and steps

dymo.com

* when compared to creating labels on an XTL label maker without templates

DYMO®



DYMO® ID - ACHIEVING LABELLING SIMPLICITY JUST GOT EASIER.

Using DYMO ID is easy thanks to a uniform experience that integrates the same great features found on your XTL™ label maker and packs them into a powerful PC-based software package. Once you've used an XTL label maker, learning to use DYMO ID will be a breeze. Available as a free download from dymo.com, DYMO ID will provide you with the functionality you need to tackle even the most complex labelling.

QUICKLY IMPORT DATA

to create a series of labels in just a few steps to eliminate manual entry, saving time and increasing productivity



OVER 200 PRE-LOADED SYMBOLS & IMAGES

or simply add a custom image to enhance communication and meet industry standards



SHEET LABELS

Quickly print XTL label maker Laminated Wire/Cable Wrap sheet labels directly to a laser printer



QUICK CUSTOMISATION & UPGRADES

Simply plug your XTL into a PC and use DYMO® ID software to customize your preferences and keep it up to date

DYMO ID WORKS WITH THE FOLLOWING:

- XTL 300 Label Maker
- XTL 500 Label Maker
- XTL Laminated Wire/Cable Wrap Sheet Labels
- Works with Windows®7 and later

AND

NOW WITH FLUKE LINKWARE™:

Fully integrated with connectivity to Fluke Networks LinkWare™ Live, DYMO® ID labelling software and XTL label-makers offer a simplified solution for cable label creation.



- Quickly connect to LinkWare™ Live to access and view the most recent project data
- Import data from a LinkWare™ Live account in just a few steps to eliminate manual entry, saving time and increasing productivity
- Use Cable ID data with built-in label applications and time-saving templates for patch panels, wire/cable labels and more
- Life-like on screen print preview shows exactly how labels will look when applied to cables, panels and more
- Print directly or transfer labels to an XTL label-maker for editing and printing in the field

XTL™

Selection Guide



	XTL™ 300	XTL™ 500
Printing System	Thermal Transfer	Thermal Transfer
Max Label Width	24 mm	54 mm
Labels Supported	DYMO XTL	DYMO XTL
Display	71.12 mm Colour	109.22 mm Colour Touch Screen
Print Speed (average)	23 mm/sec	28 mm/sec
Keyboard	QWERTY	QWERTY
Print DPI	300	300
Printable Lines	11	24
Barcodes Supported	Code 128 (Auto), Code 39, Code 39 Mod 43, EAN8, EAN13, UPC-A, Codabar, PDF-417, QR Code	Code 128 (Auto), Code 39, Code 39 Mod 43, EAN8, EAN13, UPC-A, Codabar, PDF-417, QR Code
Serialization	Yes	Yes
Cutter	Manual, Replaceable	Auto, Replaceable
Power Supply	Rechargeable Lithium Polymer Battery or AC Adapter	Rechargeable Lithium Polymer Battery or AC Adapter
Memory	41 MB	41 MB
Warranty	3 + 1 Year Limited	3 + 1 Year Limited
PC Connectivity	YES	YES
Software	DYMO ID, free download	DYMO ID, free download
Compatibility	Windows® 7 and later	Windows® 7 and later
Pack Contents	<ul style="list-style-type: none"> • DYMO XTL 300 Label Maker • AC Charging Adapter • USB Cable • Rechargeable Lithium Polymer Battery • (1) 24 mm x 7 m All-Purpose Vinyl, Black/White • Lanyard • Quick Start Guide • Software Download Card <p>Kit includes everything above, plus:</p> <ul style="list-style-type: none"> • Carrying Case • (1) 21 mm x 39 mm Laminated Wire/Cable Wrap, Black/White, 150 labels 	<ul style="list-style-type: none"> • DYMO XTL 500 Label Maker • Carrying Case • AC Charging Adapter • USB Cable • Rechargeable Lithium Polymer Battery • (1) 54 mm x 7 m All-Purpose Vinyl, Black/White • (1) 38 mm x 39 mm Laminated Wire/Cable Wrap Black/White, 150 labels • Quick Start Guide • Software Download Card

LABEL APPLICATIONS		
110 & Terminal Blocks	✓	✓
Arc Flash		✓
Asset Tracking	✓	✓
Breaker	✓	✓
Cable Wrap	✓	✓
Distribution Panel	✓	✓
Flag	✓	✓
General Label	✓	✓
Heat-Shrink Tube	✓	✓
Materials Management	✓	✓
Patch Panel	✓	✓
Pipe Marking		✓
Quick Label	✓	✓
Safety		✓

DYMO

XTLTM

MORE VERSATILITY.


THE RIGHT LABEL



DELIVERING VERSATILITY AND DURABILITY, NO MATTER WHAT THE TASK.

DYMO XTLTM labels are durable and made for a variety of surfaces. Whether you are labelling to OSHA, ISO and ANSI colour standards or labelling in harsh conditions, DYMO XTL labels have you covered. Jobsite-tested and UL-recognised, these labels won't smear or fade. Compatible with DYMO XTL label makers.

ONE LABEL SYSTEM. COUNTLESS APPLICATIONS.

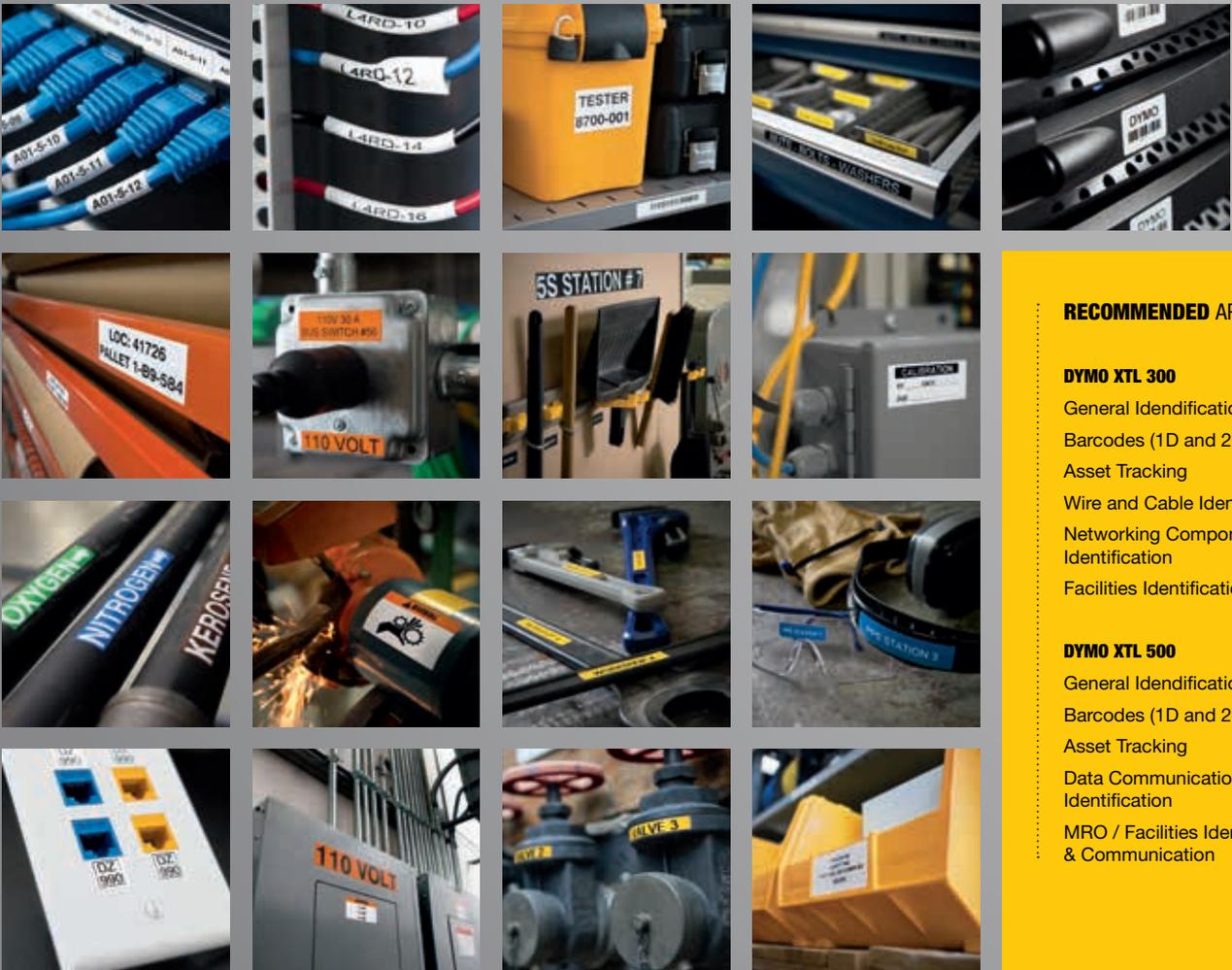

RECOMMENDED APPLICATIONS:

DYMO XTL 300

- General Identification
- Barcodes (1D and 2D)
- Asset Tracking
- Wire and Cable Identification
- Networking Components Identification
- Facilities Identification

DYMO XTL 500

- General Identification
- Barcodes (1D and 2D)
- Asset Tracking
- Data Communications Identification
- MRO / Facilities Identification & Communication



XTL LABELS

Industrial-strength labels withstand the toughest conditions – moisture, chemicals, a wide range of temperatures, UV light and more.

- Durable thermal transfer printing technology – label text won't smear or fade
- Easy-to-peel split back design and pre-sized labels make applying labels quick and easy



ALL-PURPOSE VINYL

- Moisture, chemical and UV resistance makes vinyl ideal for indoor/outdoor use
- Wide range of colours that fit with OSHA, ANSI and ISO colour standards to enhance workplace communication and safety
- UL recognised as a component to UL 969



FLEXIBLE CABLE WRAPS

- For labelling wires, cables and rounded surfaces, flexible nylon material is designed to conform and stick
- Tear-proof material resists damage when pulled through tight spaces or conduits
- UL recognised as a component to UL 969



LAMINATED WIRE/CABLE WRAPS

- Pre-sized wire/cable wraps with laminated overwrap protect printed areas from oil, chemicals, moisture, abrasion and fading
- Also available in sheet label formats for high-volume installations
- UL recognised as a component to UL 969



PRE-SIZED SAFETY LABELS

- Specific labels with coloured headers including labels pre-printed with DANGER and NOTICE headers for on-demand printing of small format safety signage
- UL recognised as a component to UL 969



PERMANENT FLAT SURFACE

- For labelling panels, blocks, faceplates, shelves, bins, beams and more
- For labelling flat surfaces, a glossy finish leaves a professional look
- UL recognised as a component to UL 969



HEAT-SHRINK TUBES (CONTINUOUS AND PRE-SIZED)

- Heat-Shrink Tubes provide insulation when shrunk down and ensure a secure fit on wires and cables with a 3:1 shrink ratio
- Meets MIL-M-81531, MIL-STD-202G, SAE-DTL-23053/5 (Class 1 & 3)
- UL recognised as a component to UL 224




PRE-SIZED LABELS

- Ideal for flat surface labelling like barcodes, faceplates, shelves, bins, beams and more
- Pre-Sized labels help facilitate batch label printing to improve productivity
- UL recognised as a component to UL 969



XTL LABELS: A VISUAL GUIDE

LABEL WIDTHS

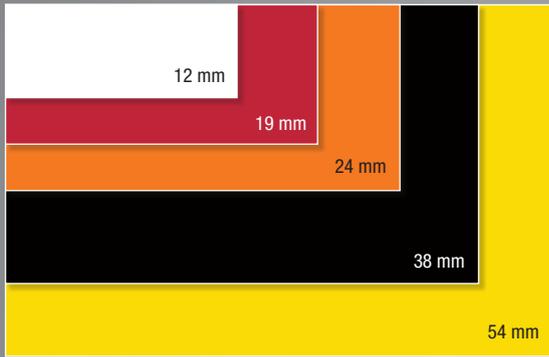

ALL-PURPOSE VINYL COLOURS



PRE-SIZED LABELS



8931558 / 12 mm x 12 mm

8931551 / 12 mm x 25 mm

8931555 / 12 mm x 38 mm

PRE-SIZED SAFETY LABELS



8931612 / 51 mm x 102 mm



 
8931621 / 51 mm x 102 mm

PRE-SIZED HEAT-SHRINK TUBE



8931646 / 24 mm x 47 mm Black on White

LAMINATED WIRE/CABLE WRAPS



8931595 / 38 mm x 39 mm

PERMANENT FLAT SURFACE



8931652 / 9 mm Black on White



8931662 / 12 mm Black on Clear

THE RIGHT LABEL FOR THE RIGHT APPLICATION.

		All-Purpose Vinyl	Permanent Flat Surface	Flexible Cable Wrap	Heat-Shrink Tube (continuous & pre-sized)	Laminated Wire/Cable Wraps	Pre-Sized Labels	Pre-Sized Safety Labels
Surface	Flat	✓	✓	✓			✓	✓
	Wires & Cables	✓		✓	✓	✓		
	Curved	✓		✓				
	Flag	✓		✓				
	Textured	✓	✓	✓			✓	✓
Resistance	Heat/Cold	-40° to 60° C	-40° to 60° C	-40° to 60° C	Max 125° C	-40° to 60° C	-40° to 60° C	-40° to 60° C
	Outdoor	✓	✓				✓	✓
	UV Light	✓	✓	✓	✓	✓	✓	✓
	Oil	✓	✓		✓	✓	✓	
	Water	✓	✓		✓	✓	✓	✓
	Chemical	✓	✓		✓	✓	✓	
Industry Standards & Ratings	Colour	OSHA, ANSI, ISO colour standards						Coloured headers to comply with OSHA, ANSI, ISO colour standards
	UL Recognised as a component to	UL 969	UL 969	UL 969	UL 224	UL 969	UL 969	UL 969
	MIL-Spec & SAE				MIL-M-8153 MIL-STD-202G SAE-DTL-230535 (Class 1 & 3)			
	RoHS	✓	✓	✓	✓	✓	✓	✓



DYMO®



CONTINUOUS & PRE-SIZED LABELS



All-Purpose Vinyl



Flexible Cable Wrap



Permanent Flat Surface



Heat-Shrink Tube (continuous)

Text Colour on Label Colour	Length	6 mm	9 mm	12 mm	19 mm	24 mm	38 mm	54 mm
-----------------------------	--------	------	------	-------	-------	-------	-------	-------

ALL-PURPOSE VINYL

ABC	7 m	-	-	8931671	8931674	8931678	8931687	8931680
ABC	7 m	-	-	8931684	8931693	8931696	8931690	8931700
ABC	7 m	-	-	8931703	8931707	8931716	8931719	8931713
ABC	7 m	-	-	8931722	8931725	8931729	8931738	8931731
ABC	7 m	-	-	8931735	8931744	8931747	8931741	8931750
ABC	7 m	-	-	8931753	8931757	8931766	8931769	8931763
ABC	7 m	-	-	8931772	8931775	8931779	8931788	8931781
ABC	7 m	-	-	8931785	8931794	8931797	8931791	8931801
ABC	7 m	-	-	8931804	8931808	8931817	8931810	8931814
ABC	7 m	-	-	8931823	8931826	8931820	8931839	8931832
ABC	7 m	-	-	8931836	8931845	8931848	8931842	8931851
ABC	7 m	-	-	8931854	8931858	8931867	8931860	8931864
ABC	7 m	-	-	8931873	8931876	8931870	8931889	8931882

PERMANENT FLAT SURFACE

ABC	9.1 m	8931659	8931652	8931656	-	-	-	-
ABC	9.1 m	8931665	8931668	8931662	-	-	-	-

FLEXIBLE CABLE WRAP

ABC	5.5 m	-	-	8931886	8931895	8931898	-	-
-----	-------	---	---	---------	---------	---------	---	---

HEAT-SHRINK TUBE (CONTINUOUS)

ABC	2.7 m	8931892	-	8931902	-	8931905	-	8931909*
-----	-------	---------	---	---------	---	---------	---	----------

*Tape length 1.8 m for #1868812 only



Heat-Shrink Tube
(pre-sized)



Pre-Sized
Labels



Pre-Sized
Safety Labels



Laminated
Wire/Cable Wraps



Laminated Wire/Cable Wraps
(sheet labels)

Text Colour on Label Colour	Item #	Label Width	Label Length	Labels / Cartridge	Compatible Label Maker
-----------------------------	--------	-------------	--------------	--------------------	------------------------

PRE-SIZED HEAT-SHRINK TUBE

ABC	8931624	6 mm	34 mm	81	XTL 500
ABC	8931628	12 mm	34 mm	65	XTL 500
ABC	8931637	24 mm	34 mm	60	XTL 500
ABC	8931630	54 mm	34 mm	25	XTL 500
ABC	8931634	6 mm	47 mm	81	XTL 500
ABC	8931643	12 mm	47 mm	65	XTL 500
ABC	8931646	24 mm	47 mm	60	XTL 500
ABC	8931640	54 mm	47 mm	25	XTL 500

PRE-SIZED LABELS

ABC	8931558	12 mm	12 mm	250	XTL 300, XTL 500
ABC	8931551	12 mm	25 mm	250	XTL 300, XTL 500
ABC	8931555	12 mm	38 mm	185	XTL 300, XTL 500
ABC	8931564	25 mm	25 mm	250	XTL 500
ABC	8931567	9 mm	25 mm	250	XTL 300, XTL 500
ABC	8931561	12 mm	19 mm	250	XTL 300, XTL 500
ABC	8931570	19 mm	25 mm	250	XTL 300, XTL 500
ABC	8931573	25 mm	51 mm	100	XTL 500
ABC	8931577	51 mm	76 mm	100	XTL 500

PRE-SIZED SAFETY LABELS (WITH COLOURED HEADERS)

ABC	8931615	51 mm	102 mm	70	XTL 500
ABC	8931618	51 mm	102 mm	70	XTL 500
ABC	8931612	51 mm	102 mm	70	XTL 500
ABC	8931621	51 mm	102 mm	70	XTL 500

LAMINATED WIRE/CABLE WRAPS

ABC	8931586	21 mm	21 mm	250	XTL 300, XTL 500
ABC	8931589	21 mm	39 mm	150	XTL 300, XTL 500
ABC	8931583	21 mm	102 mm	75	XTL 300, XTL 500
ABC	8931592	38 mm	21 mm	250	XTL 500
ABC	8931595	38 mm	39 mm	150	XTL 500
ABC	8931599	38 mm	102 mm	75	XTL 500
ABC	8931609	51 mm	21 mm	250	XTL 500
ABC	8931602	51 mm	39 mm	100	XTL 500
ABC	8931606	51 mm	102 mm	70	XTL 500

LAMINATED WIRE/CABLE WRAPS (SHEET LABELS)

Text Colour on Label Colour	SKU #	Label Width	Label Length	Labels/Sheet	Sheets/Pack	Labels/Pack
ABC	8931918	24 mm	23 mm	96	27	2592
ABC	8931911	24 mm	42 mm	48	53	2544
ABC	8931915	24 mm	103 mm	16	63	1008
ABC	8931924	41 mm	23 mm	60	34	2040
ABC	8931927	41 mm	42 mm	30	34	1020
ABC	8931921	54 mm	23 mm	36	28	1008
ABC	8931930	54 mm	42 mm	18	56	1008

dymo.com

